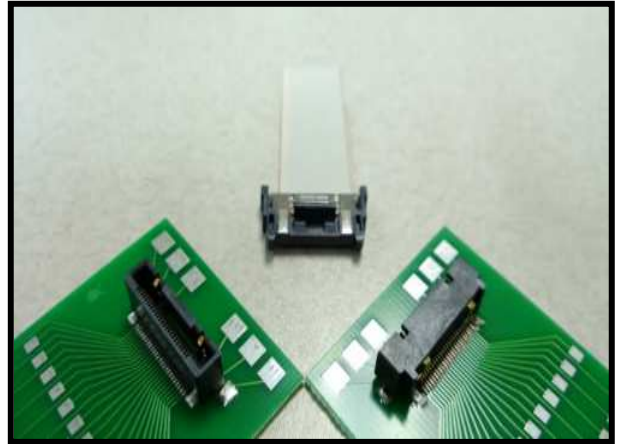


 
 
 
 
 
 
Blind-Mate FFC Connector

Product Features:

- Blind-Mating Capability
- Secured Lock Feature
- Audible Click Feedback for Perfect Mating Result
- Supports 24, 32, and 50 pin Design
- Connector has GND connection feature for Shield FFC.



Complete CNU018 Series Component List

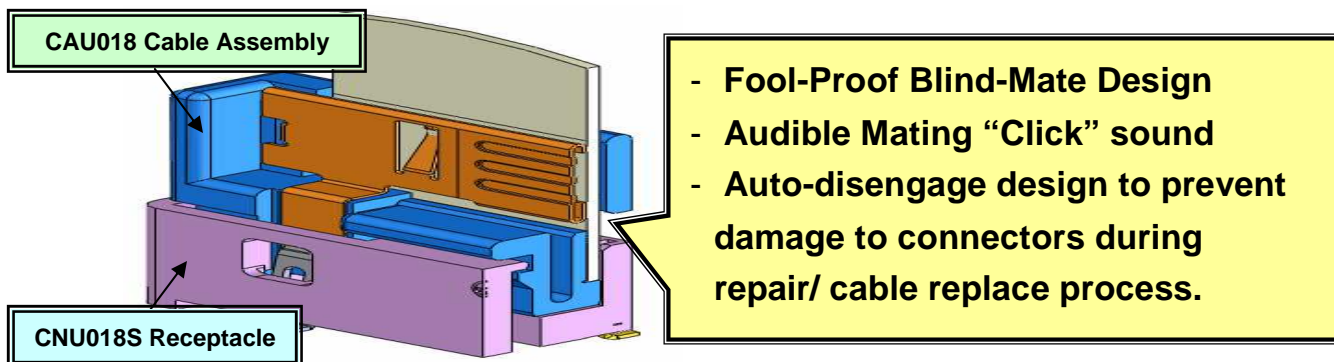
Part Number	Pin Count	Component Description	Picture
CNU018S-0**-0001	24, 32, 50	Host Connector, Vertical Mount, SMT Type	
CNU018S-0**-0011		Host Connector, Vertical Mount, T/H Type	
CNU018S-0**-0002		Host Connector, Right Angle Mount, SMT Type	
CNU018S-0**-0012		Host Connector, Right Angle Mount, T/H Type	
CNU018P-0**-0001		Plug Adaptor for FFC Cable	
CNU018P-0**-01SH		Plug Adaptor Metal Shell (Optional)	

Blind-Mate FFC Connector **CAU018 Cable Assembly Products**

Part Number	Pin Count	Cable Length	Metal Shell cover
CAU018-0XX-01-1	024 = 24pin	100mm L	N/A
CAU018-0XX-01-2		100mm L	Yes
CAU018-0XX-02-1		200mm L	N/A
CAU018-0XX-02-2		200mm L	Yes
CAU018-0XX-03-1	032 = 32pin	300mm L	N/A
CAU018-0XX-03-2		300mm L	Yes
CAU018-0XX-04-1	050 = 50pin	400mm L	N/A
CAU018-0XX-04-2		400mm L	Yes
CAU018-0XX-05-1		500mm L	N/A
CAU018-0XX-05-2		500mm L	Yes

CAU018 Series is made with CNU018P plug adaptors. For more information, please contact YEU Sales Representatives

CNU018 Series Products Design Features



CNU018 Product Series are designed to be the perfect blind-mate FFC connectors. With keyed insulator design for blind-mate function and special auto-disengage function, the product series provides reliable mating quality and durability for product maintenance/replace purposes.