


Item no.: 231-703/026-000
 Product description: FEMALE CONNECTOR 3 POLE PIN SPACING 7.62 MM / 0.3 IN WITH CODING FINGERS CLOSED END

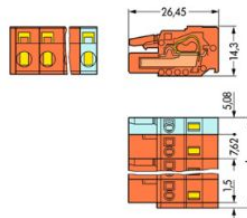

Produkt kann von Bild abweichen / product may differ

Packing unit 50 pieces

RoHS compliant

Product group	3 (Multi Conn. System)
Weight	6.25 g
Color	orange
No. of connection Points	3
No. of potentials	3
pole count	3
Height	14.3 mm
Height	0.563 in
Width	21.82 mm
Width	0.859 in
Depth	26.45 mm
Depth	1.041 in
Pin spacing from	7.62 mm
Pin spacing from	0.3 in
Pollution degree	2
Measured voltage EN	630 V
Measured shock voltage	6 kV
Current intensity EN	16 A
Pollution degree	2

Measured voltage EN	1000 V
Measured shock voltage	6 kV
Current intensity EN	16 A



Connection method	CAGE CLAMP® CONNECTION
Cross section [mm ²]	0.08 - 2.5 mm ²
Wiring method	solid
Cross section [mm ²]	0.08 - 2.5 mm ²
Cross section [mm ²]	0.25 - 1.5 mm ²
Cross section [mm ²]	0.25 - 2.5 mm ²
Cross section [AWG]	28 - 12 AWG
Strip length from	8 mm
Strip length to	9 mm
Material group	I
xxx-xxx/033-000	Strain relief plate 20 mm



Item no.	Admission office	Approval no.	Voltage [V]	Current [A]	Cross section [mm ²]
231-703/026-000	ABS	04-HG469925/1-PDA	400	16	
231-703/026-000	BV	11915/A0	400	16	2,5
231-703/026-000	CCA	5764	400	16	0,08-2,5
231-703/026-000	CSA	154112-1466354	300	15	22-12
231-703/026-000	GL	17296-00HH	400	16	
231-703/026-000	KEMA	2083746.02	400	16	0,08-2,5
231-703/026-000	KR	HMB05880-EL003	250/400	12/16	2,5
231-703/026-000	LR	96/20035	400	16	
231-703/026-000	RMR	11130002	400	16	
231-703/026-000	UR	E45171	600	15	28-12
231-703/026-000	UR	E45172	300	15	22-12

Sorting criteria: admission office - approval number

© WAGO Kontakttechnik GmbH & Co. KG

Specifications are subject to changes and errors may be expected