

Laser Materials

Laser Label Materials

Brady continues to stock the following laser toner printable labels.

Laser Printer Sheets - General ID Label Sheets

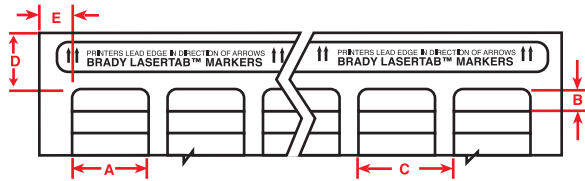


Fig. Laser-01

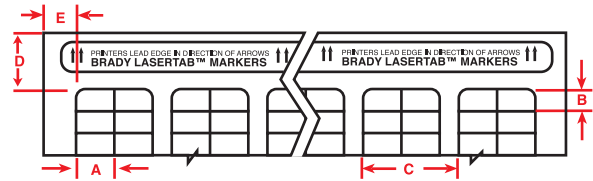


Fig. Laser-02

Diagram	Catalog #	Material	Color	Label Width A Inch (mm)	Label Height B Inch (mm)	Horizontal Repeat C Inch (mm)	Horizontal Margin E Inch (mm)	Top Margin F Inch (mm)	Labels Per Row	Labels Per Sheet	Labels Per Pkg
Laser-02	LAT-26-747-10	Polyester	White	0.250 (6.35)	0.250 (6.35)	0.600 (15.24)	0.875 (22.23)	0.400 (10.16)	26	936	10,000
Laser-02	LAT-1-747-10	Polyester	White	0.300 (7.62)	0.250 (6.35)	0.700 (17.78)	0.875 (22.23)	0.450 (11.43)	22	836	10,000
Laser-01	LAT-2-747-10	Polyester	White	0.375 (9.53)	0.375 (9.53)	0.500 (12.70)	0.875 (22.23)	0.313 (7.95)	16	400	10,000
Laser-01	LAT-45-707-10	Polyester	White	0.500 (12.70)	0.375 (9.53)	0.600 (15.24)	0.875 (22.23)	0.400 (10.16)	13	325	10,000
Laser-01	LAT-25-747-10	Polyester	White	0.500 (12.70)	0.437 (11.10)	0.600 (15.24)	0.875 (22.23)	0.400 (10.16)	13	286	10,000
Laser-01	LAT-46-707-10	Polyester	White	0.500 (12.70)	0.500 (12.70)	0.600 (15.24)	0.875 (22.23)	0.400 (10.16)	13	247	10,000
Laser-01	LAT-40-799-1	Nylon Cloth	White	0.500 (12.70)	0.750 (19.05)	0.600 (15.24)	0.875 (22.23)	0.400 (10.16)	13	156	1,000
Laser-01	LAT-40-799-5	Nylon Cloth	White	0.500 (12.70)	0.750 (19.05)	0.600 (15.24)	0.875 (22.23)	0.400 (10.16)	13	156	5,000
Laser-01	LAT-38-799-2.5	Nylon Cloth	White	0.500 (12.70)	1.437 (36.50)	0.600 (15.24)	0.875 (22.23)	0.300 (7.62)	13	78	2,500
Laser-01	LAT-3-410-10	Polyolefin	White	0.650 (16.51)	0.250 (6.35)	0.800 (20.32)	0.875 (22.23)	0.325 (8.26)	10	380	10,000
Laser-01	LAT-3-747-10	Polyester	White	0.650 (16.51)	0.250 (6.35)	0.800 (20.32)	0.875 (22.23)	0.325 (8.26)	10	380	10,000
Laser-01	LAT-29-747-10	Polyester	White	0.650 (16.51)	0.200 (5.08)	0.800 (20.32)	0.875 (22.23)	0.325 (8.26)	10	480	10,000
Laser-01	LAT-29-799-10	Nylon Cloth	White	0.650 (16.51)	0.200 (5.08)	0.800 (20.32)	0.875 (22.23)	0.325 (8.26)	10	480	10,000
Laser-01	LAT-4-410-10	Polyolefin	White	0.800 (20.32)	0.250 (6.35)	1.000 (25.40)	0.875 (22.23)	0.350 (8.89)	8	304	10,000
Laser-01	LAT-4-747-10	Polyester	White	0.800 (20.32)	0.250 (6.35)	1.000 (25.40)	0.875 (22.23)	0.350 (8.89)	8	304	10,000
Laser-01	LAT-5-747-10	Polyester	White	0.800 (20.32)	0.500 (12.70)	1.000 (25.40)	0.875 (22.23)	0.350 (8.89)	8	152	10,000
Laser-01	LAT-5-759-10	Paper	White	0.800 (20.32)	0.500 (12.70)	1.000 (25.40)	0.875 (22.23)	0.350 (8.89)	8	152	10,000
Laser-01	LAT-37-799-1	Nylon Cloth	White	0.800 (20.32)	1.437 (36.50)	0.900 (22.86)	0.875 (22.23)	0.300 (7.62)	9	54	1,000
Laser-01	LAT-37-799-2.5	Nylon Cloth	White	0.800 (20.32)	1.437 (36.50)	0.900 (22.86)	0.875 (22.23)	0.300 (7.62)	9	54	2,500
Laser-01	LAT-6-747-10	Polyester	White	1.000 (25.40)	0.250 (6.35)	1.100 (27.94)	0.875 (22.23)	0.450 (11.43)	7	266	10,000
Laser-01	LAT-8-707-10	Polyester	White	1.000 (25.40)	0.375 (9.53)	1.100 (27.94)	0.875 (22.23)	0.450 (11.43)	7	175	10,000
Laser-01	LAT-8-747-10	Polyester	White	1.000 (25.40)	0.375 (9.53)	1.100 (27.94)	0.875 (22.23)	0.450 (11.43)	7	175	10,000
Laser-01	LAT-8-799-10	Nylon Cloth	White	1.000 (25.40)	0.375 (9.53)	1.100 (27.94)	0.875 (22.23)	0.450 (11.43)	7	175	10,000
Laser-01	LAT-7-410-10	Polyolefin	White	1.000 (25.40)	0.500 (12.70)	1.100 (27.94)	0.875 (22.23)	0.450 (11.43)	7	133	10,000
Laser-01	LAT-7-707-10	Polyester	White	1.000 (25.40)	0.500 (12.70)	1.100 (27.94)	0.875 (22.23)	0.450 (11.43)	7	133	10,000
Laser-01	LAT-7-747-10	Polyester	White	1.000 (25.40)	0.500 (12.70)	1.100 (27.94)	0.875 (22.23)	0.450 (11.43)	7	133	10,000
Laser-01	LAT-7-799-10	Nylon Cloth	White	1.000 (25.40)	0.500 (12.70)	1.100 (27.94)	0.875 (22.23)	0.450 (11.43)	7	133	10,000
Laser-01	LAT-39-799-1	Nylon Cloth	White	1.000 (25.40)	1.437 (36.50)	1.100 (27.94)	0.875 (22.23)	0.300 (7.62)	7	42	1,000
Laser-01	LAT-39-799-2.5	Nylon Cloth	White	1.000 (25.40)	1.437 (36.50)	1.100 (27.94)	0.875 (22.23)	0.300 (7.62)	7	42	2,500
Laser-01	LAT-9-747-10	Polyester	White	1.500 (38.10)	0.250 (6.35)	1.600 (40.64)	0.875 (22.23)	0.300 (7.62)	5	190	10,000
Laser-01	LAT-9-799-10	Nylon Cloth	White	1.500 (38.10)	0.250 (6.35)	1.600 (40.64)	0.875 (22.23)	0.300 (7.62)	5	190	10,000
Laser-01	LAT-41-707-10	Polyester	White	1.500 (38.10)	0.375 (9.53)	1.600 (40.64)	0.875 (22.23)	0.300 (7.62)	5	125	10,000
Laser-01	LAT-47-707-10	Polyester	White	1.500 (38.10)	0.500 (12.70)	1.600 (40.64)	0.875 (22.23)	0.300 (7.62)	5	100	10,000
Laser-01	LAT-10-747-10	Polyester	White	1.875 (47.63)	0.250 (6.35)	2.000 (50.80)	0.875 (22.23)	0.314 (7.98)	4	156	10,000
Laser-01	LAT-11-747-5	Polyester	White	1.875 (47.63)	0.375 (9.53)	2.000 (50.80)	0.875 (22.23)	0.310 (7.87)	4	100	5,000
Laser-01	LAT-13-410-2.5	Polyolefin	White	1.875 (47.63)	0.833 (21.16)	2.000 (50.80)	0.834 (21.18)	0.310 (7.87)	4	44	2,500
Laser-01	LAT-13-747-2.5	Polyester	White	1.875 (47.63)	0.833 (21.16)	2.000 (50.80)	0.834 (21.18)	0.310 (7.87)	4	44	2,500
Laser-01	LAT-13-759-2.5	Paper	White	1.875 (47.63)	0.833 (21.16)	2.000 (50.80)	0.834 (21.18)	0.310 (7.87)	4	44	2,500
Laser-01	LAT-14-747-1.5	Polyester	White	1.875 (47.63)	1.330 (33.78)	2.000 (50.80)	0.834 (21.18)	0.315 (8.00)	4	28	1,500
Laser-01	LAT-31-747-1	Polyester	White	2.000 (50.80)	0.900 (22.86)	2.800 (71.12)	0.875 (22.23)	0.300 (7.62)	3	30	1,000
Laser-01	LAT-33-707-1	Polyester	White	2.000 (50.80)	1.437 (36.50)	2.800 (71.12)	0.875 (22.23)	0.300 (7.62)	3	18	1,000
Laser-01	LAT-33-747-1	Polyester	White	2.000 (50.80)	1.437 (36.50)	2.800 (71.12)	0.875 (22.23)	0.300 (7.62)	3	18	1,000
Laser-01	LAT-21-707-1	Polyester	White	2.500 (63.50)	1.000 (25.40)	2.600 (66.04)	0.875 (22.23)	0.300 (7.62)	3	27	1,000
Laser-01	LAT-21-747-1	Polyester	White	2.500 (63.50)	1.000 (25.40)	2.600 (66.04)	0.875 (22.23)	0.300 (7.62)	3	27	1,000

Laser Printer Sheets - General ID Label Sheets (cont.)

Diagram	Catalog #	Material	Color	Label Width A Inch (mm)	Label Height B Inch (mm)	Horizontal Repeat C Inch (mm)	Horizontal Margin E Inch (mm)	Top Margin F Inch (mm)	Labels Per Row	Labels Per Sheet	Labels Per Pkg
Laser-01	LAT-12-747-2.5	Polyester	White	3.000 (76.20)	0.375 (9.53)	3.200 (81.28)	0.875 (22.23)	1.150 (29.21)	2	50	2,500
Laser-01	LAT-32-747-1	Polyester	White	3.000 (76.20)	0.900 (22.86)	3.200 (81.28)	0.875 (22.23)	1.150 (29.21)	2	20	1,000
Laser-01	LAT-32-759-1	Paper	White	3.000 (76.20)	0.900 (22.86)	3.200 (81.28)	0.875 (22.23)	1.150 (29.21)	2	20	1,000
Laser-01	LAT-34-707-1	Polyester	White	3.000 (76.20)	1.437 (36.50)	3.200 (81.28)	0.875 (22.23)	1.150 (29.21)	2	12	1,000
Laser-01	LAT-34-747-1	Polyester	White	3.000 (76.20)	1.437 (36.50)	3.200 (81.28)	0.875 (22.23)	1.150 (29.21)	2	18	1,000
Laser-01	LAT-34-759-1	Paper	White	3.000 (76.20)	1.437 (36.50)	3.200 (81.28)	0.875 (22.23)	1.150 (29.21)	2	18	1,000
Laser-01	LAT-44-707-2.5	Polyester	White	3.600 (91.44)	0.375 (9.53)	-	0.650 (16.51)	0.875 (22.23)	2	40	2,500
Laser-02	LAT-26-652-10	Polyimide	Amber	0.250 (6.35)	0.250 (6.35)	0.600 (15.24)	0.875 (22.23)	0.400 (10.16)	26	936	10,000
Laser-02	LAT-1-652-10	Polyimide	Amber	0.300 (7.62)	0.250 (6.35)	0.700 (17.78)	0.875 (22.23)	0.450 (11.43)	22	836	10,000
Laser-01	LAT-2-652-10	Polyimide	Amber	0.375 (9.53)	0.375 (9.53)	0.500 (12.70)	0.875 (22.23)	0.313 (7.95)	16	400	10,000
Laser-01	LAT-25-652-10	Polyimide	Amber	0.500 (12.70)	0.437 (11.10)	0.600 (15.24)	0.875 (22.23)	0.400 (10.16)	13	286	10,000
Laser-01	LAT-3-652-10	Polyimide	Amber	0.650 (16.51)	0.250 (6.35)	0.800 (20.32)	0.875 (22.23)	0.325 (8.26)	10	380	10,000
Laser-01	LAT-29-652-10	Polyimide	Amber	0.650 (16.51)	0.200 (5.08)	0.800 (20.32)	0.875 (22.23)	0.325 (8.26)	10	480	10,000
Laser-01	LAT-4-652-10	Polyimide	Amber	0.800 (20.32)	0.250 (6.35)	1.000 (25.40)	0.875 (22.23)	0.350 (8.89)	8	304	10,000
Laser-01	LAT-5-652-10	Polyimide	Amber	0.800 (20.32)	0.500 (12.70)	1.000 (25.40)	0.875 (22.23)	0.350 (8.89)	8	152	10,000
Laser-01	LAT-6-652-10	Polyimide	Amber	1.000 (25.40)	0.250 (6.35)	1.100 (27.94)	0.875 (22.23)	0.450 (11.43)	7	266	10,000
Laser-01	LAT-8-652-10	Polyimide	Amber	1.000 (25.40)	0.375 (9.53)	1.100 (27.94)	0.875 (22.23)	0.450 (11.43)	7	175	10,000
Laser-01	LAT-7-652-10	Polyimide	Amber	1.000 (25.40)	0.500 (12.70)	1.100 (27.94)	0.875 (22.23)	0.450 (11.43)	7	133	10,000
Laser-01	LAT-9-652-10	Polyimide	Amber	1.500 (38.10)	0.250 (6.35)	1.600 (40.64)	0.875 (22.23)	0.300 (7.62)	5	190	10,000
Laser-01	LAT-10-652-10	Polyimide	Amber	1.875 (47.63)	0.250 (6.35)	2.000 (50.80)	0.875 (22.23)	0.314 (7.98)	4	156	10,000
Laser-01	LAT-12-652-2.5	Polyimide	Amber	3.000 (76.20)	0.375 (9.53)	3.200 (81.28)	0.875 (22.23)	1.150 (29.21)	2	50	2,500
Laser-01	LAT-7-773-10	Metallized Polyester	Silver	1.000 (25.40)	0.500 (12.70)	1.100 (27.94)	0.875 (22.23)	0.450 (11.43)	7	133	10,000
Laser-01	LAT-20-773-2.5	Metallized Polyester	Silver	1.500 (38.10)	0.750 (19.05)	1.600 (40.64)	0.875 (22.23)	0.250 (6.35)	5	60	2,500
Laser-01	LAT-21-773-1	Metallized Polyester	Silver	2.500 (63.50)	1.000 (25.40)	2.600 (66.04)	0.875 (22.23)	0.300 (7.62)	3	27	1,000
Laser-01	LAT-29-747-10-YL	Polyester	Yellow	0.650 (16.51)	0.200 (5.08)	0.800 (20.32)	0.875 (22.23)	0.325 (8.26)	10	480	10,000
Laser-01	LAT-7-747-10-YL	Polyester	Yellow	1.000 (25.40)	0.500 (12.70)	1.100 (27.94)	0.875 (22.23)	0.450 (11.43)	7	133	10,000
Laser-01	LAT-13-747-2.5-YL	Polyester	Yellow	1.875 (47.63)	0.833 (21.16)	2.000 (50.80)	0.834 (21.18)	0.310 (7.87)	4	44	2,500
Laser-01	LAT-21-747-1-YL	Polyester	Yellow	2.500 (63.50)	1.000 (25.40)	2.600 (66.04)	0.875 (22.23)	0.300 (7.62)	3	27	1,000
Laser-01	LAT-175-124-YL	Paper	Yellow	3.062 (77.77)	0.500 (12.70)	0.500 (12.70)	0.938 (23.83)	1.118 (30.18)	2	38	380
Laser-01	LAT-175-124-BL	Paper	Blue	3.062 (77.77)	0.500 (12.70)	0.500 (12.70)	0.938 (23.83)	1.118 (30.18)	2	38	380
Laser-01	LAT-175-124-PL	Paper	Purple	3.062 (77.77)	0.500 (12.70)	0.500 (12.70)	0.938 (23.83)	1.118 (30.18)	2	38	380
Laser-01	LAT-175-124-BR	Paper	Brown	3.062 (77.77)	0.500 (12.70)	0.500 (12.70)	0.938 (23.83)	1.118 (30.18)	2	38	380
Laser-01	LAT-175-124-GR	Paper	Green	3.062 (77.77)	0.500 (12.70)	0.500 (12.70)	0.938 (23.83)	1.118 (30.18)	2	38	380
Laser-01	LAT-175-124-GY	Paper	Gray	3.062 (77.77)	0.500 (12.70)	0.500 (12.70)	0.938 (23.83)	1.118 (30.18)	2	38	380
Laser-01	LAT-175-124-OR	Paper	Orange	3.062 (77.77)	0.500 (12.70)	0.500 (12.70)	0.938 (23.83)	1.118 (30.18)	2	38	380
Laser-01	LAT-175-124-RD	Paper	Red	3.062 (77.77)	0.500 (12.70)	0.500 (12.70)	0.938 (23.83)	1.118 (30.18)	2	38	380

Laser Printer Sheets - PermaShield™ Label Sheets

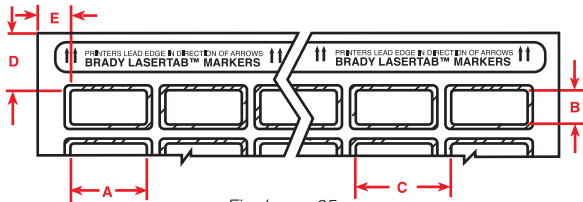


Diagram	Catalog #	Material	Color	Label Width A Inch (mm)	Label Height B Inch (mm)	Horizontal Repeat C Inch (mm)	Horizontal Margin E Inch (mm)	Top Margin F Inch (mm)	Labels Per Row	Labels Per Sheet	Labels Per Pkg
Laser-05	LAT-23-747-2.5	Polyester	White	1.000 (25.40)	0.500 (12.70)	1.350 (34.29)	1.000 (25.40)	0.275 (6.99)	6	60	2,500
Laser-05	LAT-24-747-1	Polyester	White	1.750 (44.45)	1.000 (25.40)	2.200 (55.88)	1.000 (25.40)	1.175 (29.85)	3	21	1,000
Laser-05	LAT-23-773-2.5	Metallized Polyester	Silver	1.000 (25.40)	0.500 (12.70)	1.350 (34.29)	1.000 (25.40)	0.275 (6.99)	6	60	2,500
Laser-05	LAT-24-773-1	Metallized Polyester	Silver	1.750 (44.45)	1.000 (25.40)	2.200 (55.88)	1.000 (25.40)	1.175 (29.85)	3	21	1,000