

Laser Printer Sheets - Self-Laminating Labels

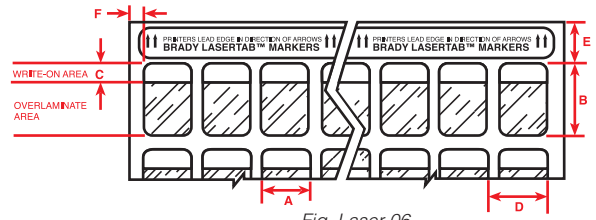


Fig. Laser-06

Diagram	Catalog #	Material	Color	Label Width A Inch (mm)	Label Height B Inch (mm)	Print-On Area C Inch (mm)	Horizontal Repeat D Inch (mm)	Horizontal Margin E Inch (mm)	Top Margin F Inch (mm)	Labels Per Row	Labels Per Sheet	Labels Per Pkg
Laser-06	LAT-15-361-1	Polyester	White/Clear	0.500 (12.70)	0.750 (19.05)	0.370 (9.40)	0.600 (15.24)	0.875 (22.23)	0.400 (10.16)	13	156	1,000
Laser-06	LAT-15-361-5	Polyester	White/Clear	0.500 (12.70)	0.750 (19.05)	0.370 (9.40)	0.600 (15.24)	0.875 (22.23)	0.400 (10.16)	13	156	5,000
Laser-06	LAT-48-361-1	Polyester	White/Clear	0.500 (12.70)	1.000 (25.40)	0.375 (9.53)	0.600 (15.24)	0.875 (22.23)	0.400 (10.16)	13	117	1,000
Laser-06	LAT-49-361-1	Polyester	White/Clear	0.500 (12.70)	1.250 (31.75)	0.500 (12.70)	0.600 (15.24)	0.875 (22.23)	0.400 (10.16)	13	91	1,000
Laser-06	LAT-22-361-5	Polyester	White/Clear	0.500 (12.70)	1.500 (38.10)	0.500 (12.70)	0.600 (15.24)	0.875 (22.23)	0.400 (10.16)	13	78	5,000
Laser-06	LAT-56-361-2.5	Polyester	White/Clear	0.600 (15.24)	1.625 (41.28)	1.000 (25.40)	1.725 (43.82)	0.875 (22.23)	0.850 (21.59)	4	64	2,500
Laser-06	LAT-59-361-2.5	Polyester	White/Clear	0.600 (15.24)	2.625 (66.68)	1.000 (25.40)	2.725 (69.22)	0.875 (22.23)	0.213 (5.41)	3	48	2,500
Laser-06	LAT-50-361-1	Polyester	White/Clear	0.750 (19.05)	1.000 (25.40)	0.375 (9.53)	0.850 (21.59)	0.875 (22.23)	0.475 (12.07)	9	81	1,000
Laser-06	LAT-51-361-1	Polyester	White/Clear	0.750 (19.05)	1.500 (38.10)	0.500 (12.70)	0.850 (21.59)	0.875 (22.23)	0.475 (12.07)	9	54	1,000
Laser-06	LAT-16-361-5	Polyester	White/Clear	1.000 (25.40)	0.750 (19.05)	0.340 (8.64)	1.100 (27.94)	0.875 (22.23)	0.450 (11.43)	7	84	5,000
Laser-06	LAT-16-361-1	Polyester	White/Clear	1.000 (25.40)	0.750 (19.05)	0.340 (8.64)	1.100 (27.94)	0.875 (22.23)	0.450 (11.43)	7	84	1,000
Laser-06	LAT-17-361-2.5	Polyester	White/Clear	1.000 (25.40)	1.000 (25.40)	0.340 (8.64)	1.100 (27.94)	0.875 (22.23)	0.450 (11.43)	7	63	2,500
Laser-06	LAT-17-361-1	Polyester	White/Clear	1.000 (25.40)	1.000 (25.40)	0.340 (8.64)	1.100 (27.94)	0.875 (22.23)	0.450 (11.43)	7	63	1,000
Laser-06	LAT-18-361-1	Polyester	White/Clear	1.000 (25.40)	1.330 (33.78)	0.500 (12.70)	1.100 (27.94)	0.834 (21.18)	0.450 (11.43)	7	49	1,000
Laser-06	LAT-18-361-2.5	Polyester	White/Clear	1.000 (25.40)	1.330 (33.78)	0.500 (12.70)	1.100 (27.94)	0.834 (21.18)	0.450 (11.43)	7	49	2,500
Laser-06	LAT-39-361-1	Polyester	White/Clear	1.000 (25.40)	1.437 (36.50)	0.500 (12.70)	1.100 (27.94)	0.875 (22.23)	0.300 (7.62)	7	42	1,000
Laser-06	LAT-58-361-1	Polyester	White/Clear	1.000 (25.40)	2.625 (66.68)	1.000 (25.40)	1.100 (27.94)	0.875 (22.23)	0.450 (11.43)	7	21	1,000
Laser-06	LAT-19-361-1	Polyester	White/Clear	1.000 (25.40)	3.167 (80.44)	0.970 (24.64)	1.100 (27.94)	0.834 (21.18)	0.450 (11.43)	7	21	1,000
Laser-06	LAT-35-361-2.5	Polyester	White/Clear	1.200 (30.48)	1.500 (38.10)	0.500 (12.70)	1.270 (32.23)	0.875 (22.23)	0.400 (10.16)	6	36	2,500
Laser-06	LAT-52-361-1	Polyester	White/Clear	1.500 (38.10)	1.000 (25.40)	0.375 (9.53)	0.875 (22.23)	0.300 (7.62)	0.300 (7.62)	5	45	1,000
Laser-06	LAT-53-361-1	Polyester	White/Clear	1.500 (38.10)	1.500 (38.10)	0.500 (12.70)	1.600 (40.64)	0.300 (7.62)	0.300 (7.62)	5	30	1,000
Laser-06	LAT-54-361-1	Polyester	White/Clear	1.750 (44.45)	1.000 (25.40)	0.375 (9.53)	0.875 (22.23)	0.600 (15.24)	0.600 (15.24)	4	36	1,000
Laser-06	LAT-55-361-1	Polyester	White/Clear	1.750 (44.45)	1.500 (38.10)	0.375 (9.53)	0.875 (22.23)	0.600 (15.24)	0.600 (15.24)	4	24	1,000
Laser-06	LAT-27-361-1	Polyester	White/Clear	1.875 (47.63)	3.167 (80.44)	0.968 (24.59)	2.000 (50.80)	0.875 (22.23)	0.215 (5.46)	4	12	1,000

Laser Printer Sheets - Non-Die-Cut Sheets

Catalog #	Material	Color	Label Width A Inch (mm)	Label Height B Inch (mm)	Labels Per Sheet	Labels Per Pkg
LAT-28-747-25-SH	Polyester	White	8.500 (215.90)	11.000 (279.40)	1	25 Sheets
LAT-28-773-25-SH	Metallized Polyester	Silver	8.500 (215.90)	11.000 (279.40)	1	25 Sheets
LAT-28-747Y-25-SH	Polyester	Yellow	8.500 (215.90)	11.000 (279.40)	1	25 Sheets

Ink Jet Label Sheets

Brady continues to stock the following ink jet labels.

Ink Jet Printers - General ID Label Sheets

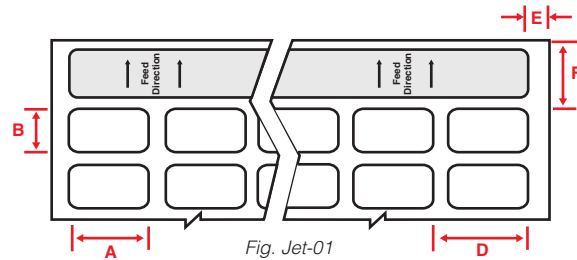


Fig. Jet-01

Diagram	Catalog #	Material	Color	Label Width A Inch (mm)	Label Height B Inch (mm)	Horizontal Repeat D Inch (mm)	Horizontal Margin E Inch (mm)	Top Margin F Inch (mm)	Labels Per Row	Labels Per Sheet	Labels Per Pkg
Jet-01	JET-11-113-10	Paper	White	0.250 (6.35)	1.000 (25.40)	0.319 (8.10)	0.750 (19.05)	0.300 (7.62)	25	225	10,000
Jet-01	JET-16-115-10	Cloth	White	0.250 (6.35)	1.500 (38.10)	0.319 (8.10)	0.750 (19.05)	0.300 (7.62)	25	150	10,000
Jet-01	JET-12-115-10	Cloth	White	0.375 (9.53)	1.000 (25.40)	0.470 (11.93)	0.750 (19.05)	0.300 (7.62)	17	153	10,000
Jet-01	JET-23-115-5	Cloth	White	0.375 (9.53)	2.000 (50.80)	0.470 (11.93)	0.750 (19.05)	0.300 (7.62)	17	68	5,000
Jet-01	JET-13-115-10	Cloth	White	0.500 (12.70)	1.000 (25.40)	0.569 (14.45)	0.750 (19.05)	0.300 (7.62)	14	126	10,000
Jet-01	JET-2-115-10	Cloth	White	0.750 (19.05)	0.500 (12.70)	0.894 (22.70)	0.750 (19.05)	0.300 (7.62)	9	153	10,000
Jet-01	JET-14-115-5	Cloth	White	0.750 (19.05)	1.000 (25.40)	0.894 (22.70)	0.750 (19.05)	0.300 (7.62)	9	81	5,000
Jet-01	JET-15-115-5	Cloth	White	0.750 (19.05)	1.250 (31.75)	0.894 (22.70)	0.750 (19.05)	0.300 (7.62)	9	63	5,000
Jet-01	JET-18-115-3	Cloth	White	0.750 (19.05)	1.500 (38.10)	0.894 (22.70)	0.750 (19.05)	0.300 (7.62)	9	54	3,000
Jet-01	JET-3-115-5	Cloth	White	1.437 (36.50)	0.500 (12.70)	1.615 (41.02)	0.750 (19.05)	0.300 (7.62)	5	59	5,000
Jet-01	JET-9-115-3	Cloth	White	1.437 (36.50)	0.800 (20.32)	1.615 (41.02)	0.750 (19.05)	0.300 (7.62)	5	55	3,000
Jet-01	JET-27-117-5	Vinyl	White	0.500 (12.70)	0.750 (19.05)	1.000 (25.40)	0.750 (19.05)	0.425 (10.79)	8	125	5,000
Jet-01	JET-29-117-3	Vinyl	White	0.500 (12.70)	1.380 (35.05)	1.600 (40.64)	0.750 (19.05)	0.425 (10.79)	5	80	3,000
Jet-01	JET-28-117-3	Vinyl	White	0.950 (24.13)	0.750 (19.05)	0.250 (6.35)	0.750 (19.05)	0.425 (10.79)	8	72	3,000
Jet-01	JET-30-117-2	Vinyl	White	0.950 (24.13)	1.380 (35.05)	1.600 (40.64)	0.750 (19.05)	0.425 (10.79)	5	45	2,000
Jet-01	JET-31-117-1	Vinyl	White	0.950 (24.13)	2.250 (57.15)	2.625 (66.67)	0.750 (19.05)	0.425 (10.79)	3	27	1,000
Jet-01	JET-33-117-1	Vinyl	White	0.950 (24.13)	3.750 (95.25)	4.000 (101.60)	0.750 (19.05)	0.425 (10.79)	3	18	1,000
Jet-01	JET-32-117-0.5	Vinyl	White	1.800 (45.72)	2.250 (57.15)	0.375 (9.52)	0.750 (19.05)	0.425 (10.79)	3	15	500
Jet-01	JET-34-117-0.5	Vinyl	White	1.800 (45.72)	3.750 (95.25)	4.000 (101.60)	0.750 (19.05)	0.425 (10.79)	2	10	500

Ink Jet Printers - Self-Laminating Label Sheets

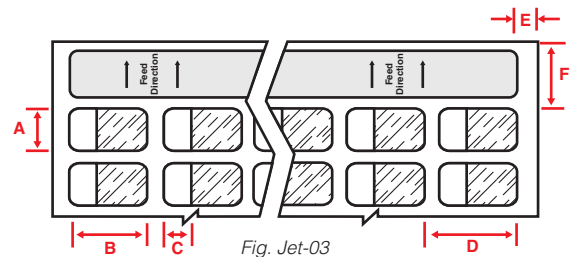


Fig. Jet-03

Diagram	Catalog #	Material	Color	Label Width A Inch (mm)	Label Height B Inch (mm)	Write-On Area C Inch (mm)	Horizontal Repeat D Inch (mm)	Horizontal Margin E Inch (mm)	Top Margin F Inch (mm)	Labels Per Row	Labels Per Sheet	Labels Per Pkg
Jet-03	JET-27-117-5	Vinyl	White	0.500 (12.70)	0.750 (19.05)	0.380 (9.65)	1.000 (25.40)	0.750 (19.05)	0.425 (10.79)	8	125	5,000
Jet-03	JET-28-117-3	Vinyl	White	0.950 (24.13)	0.750 (19.05)	0.380 (9.65)	0.250 (6.35)	0.750 (19.05)	0.425 (10.79)	8	72	3,000
Jet-03	JET-29-117-3	Vinyl	White	0.500 (12.70)	1.380 (35.05)	0.500 (12.70)	1.600 (40.64)	0.750 (19.05)	0.425 (10.79)	5	80	3,000
Jet-03	JET-30-117-2	Vinyl	White	0.950 (24.13)	1.380 (35.05)	0.500 (12.70)	1.600 (40.64)	0.750 (19.05)	0.425 (10.79)	5	45	2,000
Jet-03	JET-31-117-1	Vinyl	White	0.950 (24.13)	2.250 (57.15)	0.750 (19.05)	2.625 (66.67)	0.750 (19.05)	0.425 (10.79)	3	27	1,000
Jet-03	JET-32-117-0.5	Vinyl	White	1.800 (45.72)	2.250 (57.15)	0.750 (19.05)	0.375 (9.52)	0.750 (19.05)	0.425 (10.79)	3	15	500
Jet-03	JET-33-117-1	Vinyl	White	0.950 (24.13)	3.750 (95.25)	1.000 (25.40)	4.000 (101.60)	0.750 (19.05)	0.425 (10.79)	3	18	1,000
Jet-03	JET-34-117-0.5	Vinyl	White	1.800 (45.72)	3.750 (95.25)	1.000 (25.40)	4.000 (101.60)	0.750 (19.05)	0.425 (10.79)	2	10	500