


Data Sheet | Item Number: 210-872

Marking strips; for Smart Printer; permanent adhesive; 20 mm; white

<https://www.wago.com/210-872>

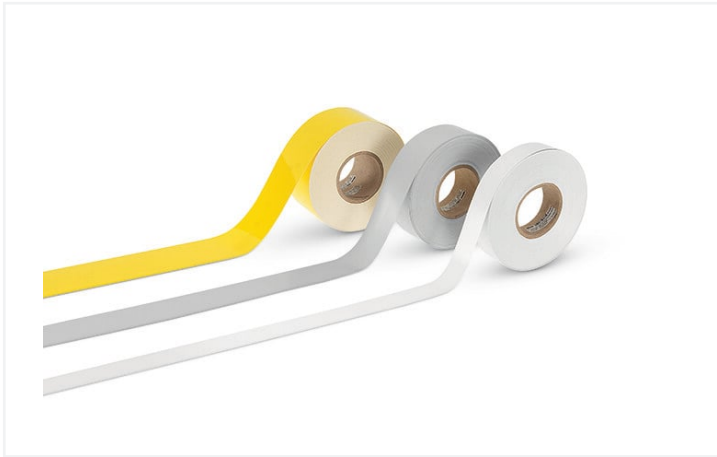

Color: ■ white

Similar to illustration

Technical data

Marking method	Thermal transfer
Marking	plain
Delivery form	Roll
Delivery form configuration	20 m; 1 line
Printing device	Smart Printer (thermal transfer printer)

Physical data

Width	20 mm
Depth	0.2 mm
Strip width	20 mm

Mechanical data

Mounting type	Sticking
Smear resistance	in conjunction with 258-5005 Ink Ribbon

Material data

Color	white
Material	Polyester
UV resistance	EN 60068-2-5:2010 Procedure B
Adhesive information	Acrylic; permanent
Halogen-free	Yes
Weight	0 g
Fire load	0 MJ

Environmental requirements

Ambient temperature (storage)	+10 ... +21 °C
Ambient temperature (operation)	-40 ... +150 °C
Relative humidity	40 ... 50 %

Commercial data

eCl@ss 10.0	27-40-06-29
eCl@ss 9.0	27-40-06-29
ETIM 8.0	EC001288
ETIM 7.0	EC001288
PU (SPU)	1 pcs
Packaging type	Box
Country of origin	DE
GTIN	4055143378895
Customs tariff number	39199080888

Environmental Product Compliance

RoHS Compliance Status	Compliant, No Exemption
------------------------	-------------------------

Downloads

Environmental Product Compliance


Compliance Search

Environmental Product
Compliance 210-872



Documentation

Operating Instructions

2009-110 Information on printing material	1 28.08.2020	pdf 1190.09 KB	
--	-----------------	-------------------	---

1 Compatible Products

1.1 Optional Accessories

1.1.1 Marking

1.1.1.1 Marking device



Item No.: 258-5000

Thermal transfer printer; Smart Printer; for complete control cabinet marking; 300 dpi; With marking material